


Specification

| Mobile Digital Video Recorder |  |
|-------------------------------|--|
| Storage media type            | SD / MMC Card slot (support up to 2GB) , Built-in flash memory 128 MB  |
| LCD display                   | 2.5" LTPS TFT LCD 960 x 240 , 230K pixels / 262K Color   |
| Interface                     | 2 in 1 MiniUSB ( USB2.0 / Power in ) ; 4 in 1 earphone jack<br>(Video out / earphone jack / external microphone / AV in)                       |
| Video out / Video in          | TV OUT ( NTSC / PAL ) / AV IN ( NTSC / PAL )   |
| Extend interface              | Extend DC power 9V out for camera and AV in  |
| AV recorder resolution        | 640 x 480 (VGA) / max 30 fps   |
| AV audio quality              | 2 modes : radio quality (16KHz) / CD quality (48KHz)   |
| AV recorder quality           | MPEG4 : best fine normal basic economy   |
| Voice recorder                | 2 modes: radio quality (16KHz)/CD quality (48KHz)  |
| Format support                | JPEG ASF WAV MP3 WMA   |
| Language support              | 12 languages: English, German, French, Spanish, Italian, Portuguese<br>, Japanese, simple Chinese, tradition Chinese, Korean, Polish, Turkey   |
| Battery                       | Rechargeable LI-ION battery<br>3.7 V /920mA , compatible with NP60 type battery  |
| Adapter                       | 5V DC adapter (USB port) / USB cable   |
| Weight(g)                     | 95g ( with battery)  |
| Size                          | 18 x 68 x 81 ( L x W x H ) mm  |
| Extend Interface              | Extend DC Power 9V out for Camera and AV in<br><br>Scheduled recording function ( 12 event )<br>Special Power save button (monitor sleep mode) |



MP-415E

Dimension

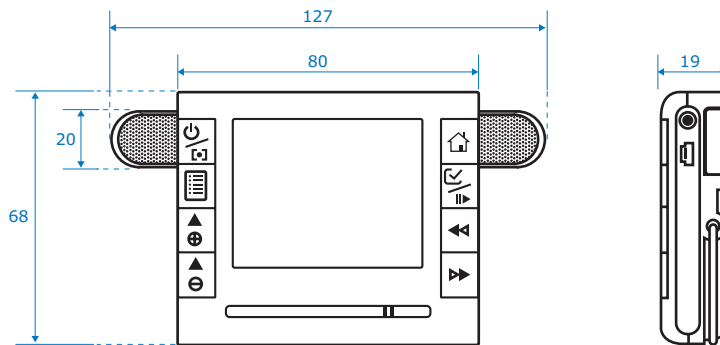

unit : mm

Other model



SS-L1475

CCD snake camera with white LED light



MO-L806

CMOS snake camera with white LED light