




Board

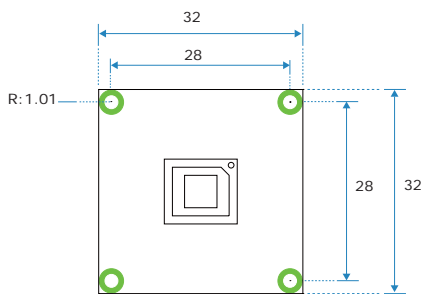

G-TYPE

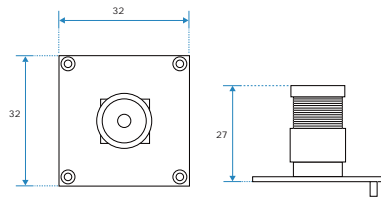

PIN HOLE LENS(3C)

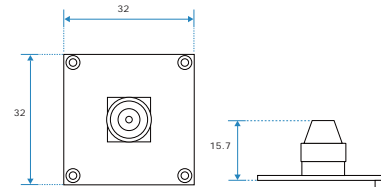

Unit : mm (± 0.5)

Feature

- Hi Resolution up to 380 TV Lines.
- Compact size.
- Ultra-lightweight!
- Backlight compensation.
- High Quality Picture.
- Outstanding Quality!

Specification

Model	N-1432G	N-1832G	N-1332G	N-1632G
Video system	NTSC / PAL			
Number of effective pixels	510x492(NTCS) , 500x528(PAL)	768x494(NTCS) , 752x582(PAL)	510x492(NTCS) , 500x528(PAL)	768x494(NTCS) , 752x582(PAL)
Image sensor	1/4" COLOR CCD Star-light CAMERA		1/3" COLOR CCD Star-light CAMERA	
Resolution(TV Lines)	380 TV Lines	520 TV Lines	420 TV Lines	570 TV Lines
S/N Ratio	more than 50dB			
Minimum illumination	0.2 LUX / F1.4			
Shutter Speed	1/50-1/100000			
Horizontal sync frequency	NTSC(EIA) -15.734kHz , PAL(CCIR) - 15.625kHz			
Vertical sync frequency	NTSC(EIA) - 60Hz , PAL(CCIR) - 50Hz			
Camera consumption	0.45			
Video output	1Vp-p , 75ohm composite			
Storage temperature	-30 to 60 Degree C			
Working temperature	-10 to 45 Degree C			
Built-in Lens	3.6 mm/F2.0			
Power source	DC 5-12 V(Standard)			
Power current	80 mA			
Dimension (mm)	32 x 32 (mm)			



G-TYPE



PIN HOLE LENS(3C)

Ordering Information

MODEL	LENS	MIC.	TYPE	MODEL	LENS	MIC.	TYPE
N-1332P-3C	3.7mm / F2.0	x	CONE	N-1332PA-3C	3.7mm / F2.0	External	CONE
N-1332P-4C	4.3mm / F2.0	x	CONE	N-1332PA-4C	4.3mm / F2.0	External	CONE
N-1332P-3F	3.7mm / F2.0	x	FLAT	N-1332PA-3F	3.7mm / F2.0	External	FLAT
N-1332P-4F	4.3mm / F2.0	x	FLAT	N-1332PA-4F	4.3mm / F2.0	External	FLAT
N-1332P-3T	3.1mm / F3.4	x	SLIM	N-1332PA-3T	3.1mm / F3.4	External	SLIM
N-1332P-4T	3.9mm / F3.9	x	SLIM	N-1332PA-4T	3.9mm / F3.9	External	SLIM
N-1332G	3.6mm / F2.0	x	G-TYPE	N-1332GA	3.6mm / F2.0	External	G-TYPE

Note:

- N-1432GA A : External Mic.
- N-1432GA Medium Resoulution 1/4" CCD Star-light Color Camera
- N-1832GA High Resoulution 1/4" CCD Star-light Color Camera
- N-1332GA Medium Resoulution 1/3" CCD Star-light Color Camera
- N-1632GA High Resoulution 1/3" CCD Star-light Color Camera

Other information

NX-1426G
 1/4" Color CCD star-light Camera

