


Feature

- Hi Resolution up to 380 TV Lines.
- Ultra Lightweight !
- Backlight compensation.
- OSD Function
- High Performance.
- Superior Quality !
- Ultra Thin !

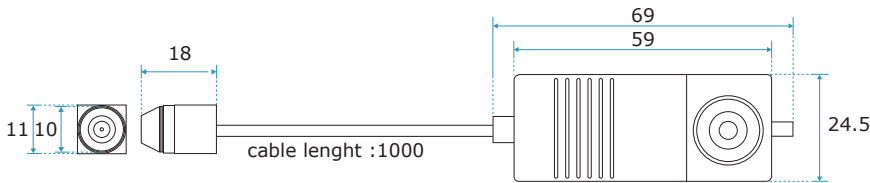

Unit : mm (± 0.5)

Specification

| | |
|----------------------------|----------------------------------|
| Model | N-1485E-3C |
| Video system | 1/4" COLOR CCD SNAKE OSD CAMERA |
| Number of effective pixels | NTSC & PAL |
| Image sensor | 510 x 492(NTSC) & 500 X 528(PAL) |
| Resolution(TV Lines) | 380 TV Lines |
| S/N Ratio | more than 48dB |
| Minimum illumination | 0.2 LUX / F1.2 |
| Shutter Speed | 1/50-1/100,000 Sec. |
| Horizontal sync frequency | NTSC - 15.734kHz , PAL-15.625kHz |
| Vertical sync frequency | NTSC - 60Hz , PAL-50Hz |
| Camera consumption | 0.45 |
| Video output | 1Vp-p , 75ohm composite |
| Built in - Lens | 3.7mm/F2.0 |
| Storage temperature | -30 to 60 Degree C |
| Working temperature | -10 to 45 Degree C |
| Power source | DC 5 ~ 12 V(Standard) |
| Power current | 80 mA |
| Dimension (mm) | 11 x 11 (mm) |



N-1485E-3C

Ordering Information

| MODEL | LENS | TYPE | MIC. | NOTE |
|--------------|-------------------------------|------|------|--|
| N-1485EYA-3C | 3.7mm / F2.0 Day & Night Lens | CONE | x | NOTE N-1485EYA-3C Y: Day & night Lens |
| N-1485EYA-4C | 4.3mm / F2.0 Day & Night Lens | CONE | x | |
| N-1485EYA-3F | 3.7mm / F2.0 Day & Night Lens | FLAT | x | N-1485EYA-3C A: External Mic. |
| N-1485EYA-4F | 4.3mm / F2.0 Day & Night Lens | FLAT | x | |
| N-1485EYA-3T | 3.1mm / F3.4 Day & Night Lens | SLIM | x | |
| N-1485EYA-4T | 3.9mm / F3.9 Day & Night Lens | SLIM | x | |

Other information

N-1871E-3C

1/4" COLOR CCD SNAKE OSD CAMERA

▼ N-1871-3C




▲ OSD Control Stick

N-1871-3C + OSD Control Stick
= **N-1871E-3C**

1/4" COLOR CCD SNAKE OSD CAMERA

N-1485-3C + OSD Control Stick = **N-1485E-3C**

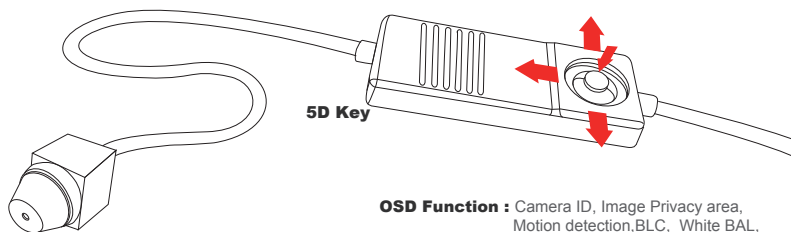

OSD Function : Camera ID, Image Privacy area, Motion detection, BLC, White BAL, Shutter Speed, AGC, Negative Image, RGB, Adjust, H Mirror, Gamma