




BOARD

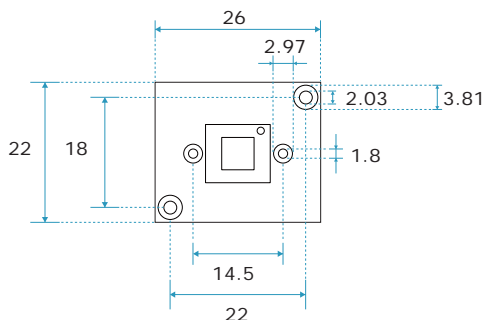

N-1426G,N-1826G

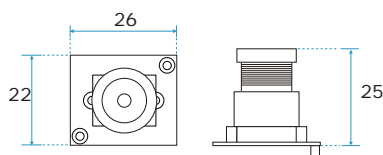

N-1426P-3F,N-1826-3F

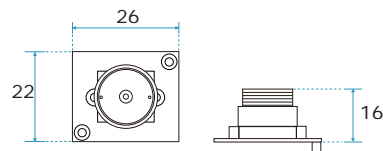

unit : mm (±0.5)

Feature

- Compact size.
- Backlight compensation.
- Superb picture quality!
- High Performance.
- Outstanding Quality!
- Competitive Price!

Specification

| Model | N-1426G | N-1826G |
|----------------------------|--|----------------------------------|
| Video system | NTSC / PAL | |
| Number of effective pixels | 510 x 492 (NTSC)/500 x 528 (PAL) | 768 x 494 (NTSC)/752 x 582 (PAL) |
| Image sensor | 1/4" CCD Color Camera | |
| Resolution(TV Lines) | 380 TV Lines | 520 TV Lines |
| S/N Ratio | more than 48dB | |
| Minimum illumination | 0.2 LUX / F1.2 | |
| Shutter Speed | 1/50-1/100,000 Sec. | |
| Horizontal sync frequency | NTSC -15.734kHz , PAL- 15.625kHz | |
| Vertical sync frequency | NTSC - 60Hz , PAL - 50Hz | |
| Camera consumption | 0.45 | |
| Video output | 1Vp-p , 75ohm composite | |
| Audio output | 20-16000Hz,S/N more than 58dB (Optional) | |
| Built - lens | 3.6mm / F2.0 | |
| Storage temperature | -30 to 60 Degree C | |
| Working temperature | -10 to 45 Degree C | |
| Power source | DC 5~ 12 V(Standard) | |
| Power current | 80 mA | |
| Dimension (mm) | 22 X 26 (mm) | 22 X 26 (mm) |



N-1426G , N-1826G



N-1426P-3F

Ordering Information

| MODEL | LENS | MIC. | TYPE | MODEL | LENS | MIC. | TYPE |
|------------|--------------|------|--------|-------------|--------------|----------|--------|
| N-1426P-3C | 3.7mm / F2.0 | x | CONE | N-1426PA-3C | 3.7mm / F2.0 | External | CONE |
| N-1426P-4C | 4.3mm / F2.0 | x | CONE | N-1426PA-4C | 4.3mm / F2.0 | External | CONE |
| N-1426P-3F | 3.7mm / F2.0 | x | FLAT | N-1426PA-3F | 3.7mm / F2.0 | External | FLAT |
| N-1426P-4F | 4.3mm / F2.0 | x | FLAT | N-1426PA-4F | 4.3mm / F2.0 | External | FLAT |
| N-1426P-3T | 3.1mm / F3.4 | x | SLIM | N-1426PA-3T | 3.1mm / F3.4 | External | SLIM |
| N-1426P-4T | 3.9mm / F3.9 | x | SLIM | N-1426PA-4T | 3.9mm / F3.9 | External | SLIM |
| N-1426G | 3.6mm / F2.0 | x | G-TYPE | N-1426GA | 3.6mm / F2.0 | External | G-TYPE |
| N-1826G | 3.6mm / F2.0 | x | G-TYPE | N-1826GA | 3.6mm / F2.0 | External | G-TYPE |

Note:

- N-1426GA-xx A : External Mic.
- N-1426GA-xx Medium Resolation 1/4" CCD Color Camera
- N-1826GA-xx High Resolation 1/4" CCD Color Camera

Other information

MO-B3526G
1/4" Color CCIQ II Camera

