


**Feature**

- Hi Resolution up to 380 TV Lines.
- Ultra Lightweight !
- Backlight compensation.
- OSD Function
- High Performance.
- Superior Quality !
- Ultra Thin !

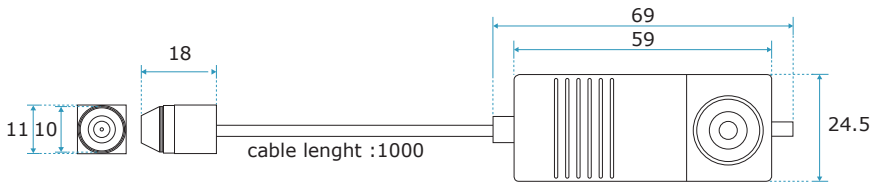

Unit : mm (± 0.5)

**Specification**

Model	SS-1485-3C
Video system	1/4" COLOR CCD SNAKE OSD CAMERA
Number of effective pixels	NTSC & PAL
Image sensor	510 x 492(NTSC) & 500 X 528(PAL)
Resolution(TV Lines)	380 TV Lines
S/N Ratio	more than 48dB
Minimum illumination	0.2 LUX / F1.2
Shutter Speed	1/50-1/100,000 Sec.
Horizontal sync frequency	NTSC - 15.734kHz , PAL-15.625kHz
Vertical sync frequency	NTSC - 60Hz , PAL-50Hz
Camera consumption	0.45
Video output	1Vp-p , 75ohm composite
Built in - Lens	3.7mm/F2.0
Storage temperature	-30 to 60 Degree C
Working temperature	-10 to 45 Degree C
Power source	DC 5 ~ 12 V(Standard)
Power current	80 mA
Dimension (mm)	11 x 11 (mm)



SS-1485-3C

**Ordering Information**

MODEL	LENS	TYPE	NOTE
SS-1485YA-3C	3.7mm / F2.0 Day & Night Lens	CONE	NOTE SS-1485YA-3C Y:Day & night Lens
SS-1485YA-4C	4.3mm / F2.0 Day & Night Lens	CONE	
SS-1485YA-3F	3.7mm / F2.0 Day & Night Lens	FLAT	SS-1485YA-3C A:External Mic.
SS-1485YA-4F	4.3mm / F2.0 Day & Night Lens	FLAT	
SS-1485YA-3T	3.1mm / F3.4 Day & Night Lens	SLIM	
SS-1485YA-4T	3.9mm / F3.9 Day & Night Lens	SLIM	

**Other information**

**N-1871E-3C**  
1/4" COLOR CCD SNAKE OSD CAMERA


▼ N-1871-3C



▲ OSD Control Stick

N-1871-3C + OSD Control Stick  
= **N-1871E-3C**

**1/4" COLOR CCD SNAKE OSD CAMERA**

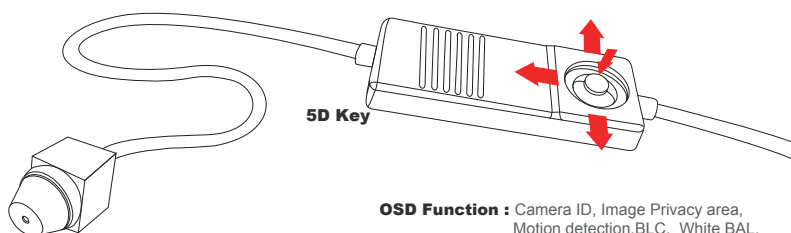

**OSD Function :** Camera ID, Image Privacy area, Motion detection, BLC, White BAL, Shutter Speed, AGC, Negative Image, RGB , Adjust, H Mirror, Gamma ....