



**Board Type**

 
**MF-200**

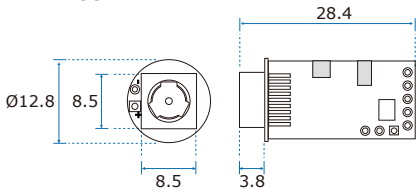

**MF-T200LW**

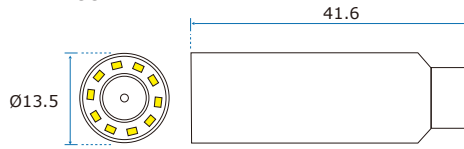

**MF-L200**




**Feature**

- AGC Auto, AES Auto!
- Compact size.
- AF (Auto Focus) VCM !
- High Performance.
- Outstanding Quality!
- Competitive Price!


UNIT:±0.5mm

**Specification**

Model	MF-200	MF-T200LW	MF-L200
Video system	NTSC / PAL		
Number of effective pixels	640 x 480 (NTSC & PAL)		
Image sensor	1/4" AF (Auto Focus) VCM CCIQIII CAMERA		
Resolution(TV Lines)	400 TV Lines		
S/N Ratio	more than 50dB		
Minimum illumination	0.1 LUX / F1.2		
Electronic shutter	60 field (NTSC) , 50 field (PAL)		
Horizontal sync frequency	NTSC(EIA) -15.734kHz , PAL(CCIR) - 15.625kHz		
Vertical sync frequency	NTSC(EIA) - 60Hz , PAL(CCIR) - 50Hz		
Camera consumption	0.45		
Video output	CVBS		
Storage temperature	-30 to 60 Degree C		
Working temperature	-10 to 45 Degree C		
Lens View Angle(Fov)	65 degree		
Lens F/NO	3.0 +- 5%		
Focal Length	7 ~ 35cm		
LED	N/A	white LED x 10	
Power source	DC 3.3~5V ( suggest DC 3.3V)		DC 5~12V
Power Consumption	250mA, 5V(1.25w)		
Dimension(mm)	Ø12.8 x 28.4mm	Ø13.5 x 41.6mm	

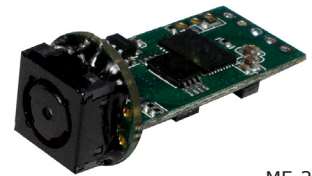

MF-200

 

MF-T200LW



MF-L200

**Other Information**

**Snake camera with LED light (Electronic MF) ▶ MO-V3575V**

- Focus adjustable (Electronic MF)
- 4 white LED (LED Light intensity Adjustable)

1/4" Color CCIQ II Camera  
Pixel : 648 x 488 (N/P)  
focus 6cm ~ infinite(VCM f 3.3mm F2.8 Lens)  
(IR LED light : 940nm or 850nm -ordering in advance)

