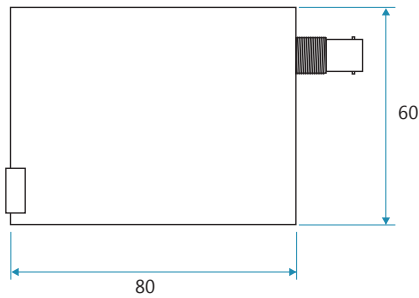


UVC (DRIVER FREE) USB 3G-SDI /HD- SDI GRABBER STICK

USD-250



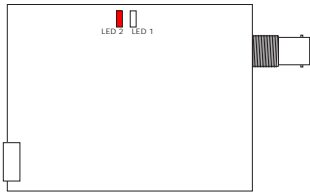
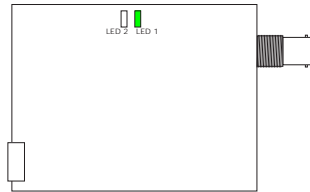
Unit : mm (±0.5)



Feature

- Driver free (USB Video Class) for any OS (win8,win8.1, MAC OS)
- Compatible for Directshow.
- Play & Plug with USB Video Class for USB 3.0
- SDI video source input , UVC for video output / UAC for Audio output
- UP to 1920X1080P 60fps YUV (No compression)

Specification

Model	USD-250M		
Pixel	3G-SDI /HD-SDI input	1920 x 1080P (60fps/50fps)	1280 x 720P (60fps/50fp)
	USB UVC output	1. YUV 1920x1080 up to 60/50fps (full screen)	1. YUV 1280x720 up to 60/50fps (full screen)
LED indicator			
Interface	USB 3.0		
USB Driver	Driver free, standard UVC1.1/UAC1.0		
Storage temperature	-30 to 60 Degree C		
Working temperature	-10 to 45 Degree C		
Power input	5V		
Power current	max is 460mA / average is 400~450 mA		
Dimension(mm)	80mm x 60mm (without connector)		
OS support	Win8.1, Win10, Mac OSX		
Weight	30g		

