


UNIT: mm

Specification

Model) A' (\$&, =: !A *
Sensor type	1/4"
Focal length	3.4mm
Image circle	Ø4.8 mm ±5%
FBFL	0.81mm ±1%
Aperture F/no	2.8 ±5%
F.O.V (D/H/V)	65.5° / 54.5° / 42.3°
Total Track	10.05mm ±1%
Mount	M6 x P0.35
Lens construction	4P
IR	650nm

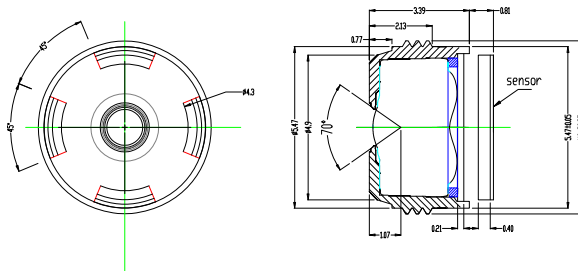

UNIT: mm

Specification

Model) A' (\$* \$=F: !A *
Sensor type	1/4"
Focal length	3.4mm
Image circle	Ø4.8 mm ±5%
FBFL	0.81mm ±1%
Aperture F/no	6.0 ±5%
F.O.V (D/H/V)	65.5° / 54.5° / 42.3°
Total Track	10.05mm ±1%
Mount	M6 x P0.35
Lens construction	4P
IR	650nm

